



## Summary

[Request a quote](#)

[Catalog](#)

Size	2T
Series	T - Small Outdoor keyed

## Technical details

### Form & Material

Shell style / Model id	BFG - Blanking cap for plugs
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	7.76 g



[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/bfg-2t-100-cas.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bfg-2t-100-cas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental protection (IP rating)	IP68
Minimal temperature	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr

## Drawings

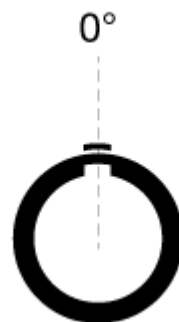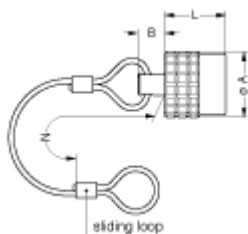

## Dimensions

	A	B	L	N
mm.	15	6	13.8	85
in.	0.59	0.24	0.54	3.35

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/bfg-2t-100-cas.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bfg-2t-100-cas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.