



Summary

[Request a quote](#)

[Catalog](#)

Size	0S
Series	S - Indoor Stepped Insert

Technical details

Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) collet and crimping tube, brass (chrome plated [SAE AMS 2460]) collet nut
Keying	Circular, female
Weight	3.62 g


https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-0s-200-nav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental protection (IP rating)	No IP rating
Minimal temperature	-40°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

Drawings

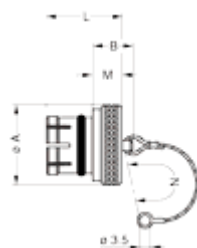

Dimensions

	A	B	L	M	N
mm.	10	9.5	10.5	4.5	85
in.	0.39	0.37	0.41	0.18	3.35

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-0s-200-nav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.