



Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	6
Wire Size/AWG	28 - 20
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	1.00 - 15.60 mm
Size	2P
Matching parts	CAB.M06.GLA.C52G
Series	REDEL P - Push-Pull

Technical details

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m06-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
Insert configuration value	2P.M06 - 6 Low V.
Insulator	L: PEEK for solder contacts
Rated current	12 Amps
Test voltage (kV rms) Contact-contact	1.35
Contact Type	Solder
Air clearance	1.1 mm
Creepage distance	1.1 mm
Bucket Dia.	1.1 mm (0.043in)
Contact Dia.	1.3 mm (0.051in)
Low Voltage	6
Wire Size/AWG	28 - 20
Gender	Standard

Form & Material

Shell style / Model id	CK - Fixed receptacle with two nuts (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	PSU (Polysulfone), gray
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=60, Plug: male contacts, Receptacle: female contacts)
Weight	5.43 g

Environment

Technical domain	Energy and Industrial, Medical, Test and Measurement, Transportation, Aerospace and UAV
Environmental protection (IP rating)	IP50
Minimal temperature	-50°C / +150°C
F ret (max)	250 N
F ret (min)	150 N
Steam sterilization	20 times



https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m06-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	1.00 - 15.60 mm

Drawings

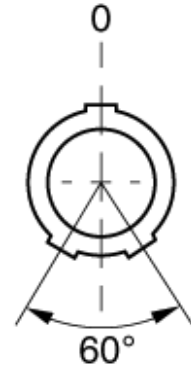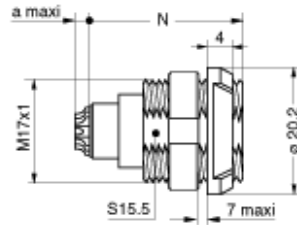

Dimensions

	N	a
mm.	23.8	3.4-4.9
in.	0.94	

Recommended By Lemo

Accessories

Tools

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m06-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.06.T20.062PGZE		grey	
CMN.06.T20.062PNZE			
CMN.06.T20.062QGZE	TPR (medical)	Grey	
CMN.06.T26.037QGZE	TPR (medical)	Grey	
CMN.06.T28.031PGCE	PVC	GREY	
CMN.06.T28.031PGZE		grey	
CMN.06.T28.031PNCE	PVC	Black	
CMN.06.T28.031PNZE			
CMN.06.T28.042QBCE	TPR (medical)		
CMN.06.T28.044PGZE		grey	
CMN.06.T28.044PNZE			
106220	PVC	Black	
106240	PTFE	White	
12080	PVC	Grey	
160140	PVC	Grey	
160240	PVC	Black	
160260	PVC	Black	
260250	PVC	Grey	
360500	PVC	Grey	
360750	PVC	Grey	
60260	PTFE	White	
6280	PVC	Black	

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m06-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.