



Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	36
Wire Size/AWG	26 - 22
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 9.20 mm
Matching parts	FGG.1R.336.GLC92

Technical details

Electrical Configuration

Contact Termination Low voltage	Crimp
Insert configuration value	1R.336 - 36 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	2.5 Amps
Test voltage (kV rms) Contact-contact	1.5
Contact Type	Crimp
Contact Dia.	0.7
Low Voltage	36
Wire Size/AWG	26 - 22

https://www.lemo.com/int_en/egg-1r-336-glm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	EGG - Fixed receptacle, key (G) or key (A)
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Crastin® PBT (Polybutylene terephthalate), gray
Locking system	Push-pull
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Weight	13.44 g



Environment

Environmental protection	IP50
--------------------------	------

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.00 - 9.20 mm

Drawings

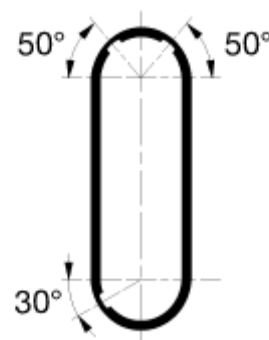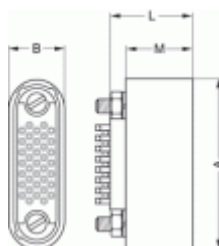

Dimensions

	A	B	L	M
mm.	37	12.5	18	14.5
in.	1.46	0.49	0.71	0.57

https://www.lemo.com/int_en/egg-1r-336-glm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.