



## Summary

[Request a quote](#)

[Catalog](#)

Coax	2
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 22.60 mm
Size	3K
Matching parts	<a href="#">FGG.3K.846.CLAC111</a>
Series	K - Outdoor keyed

## Technical details

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egg-3k-846-cll1.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-cll1.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Coax	2
Contact Termination Coax	Crimp
R (max)	5.8 mOhm
Insert configuration value	3K.846 - 2 Coax (50 Ohm), 6 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 Amps
Test voltage (kV rms)	0.9
Contact Type	Coaxial 50 Ohm (Crimp) Type C
Cable type	Cable type: A RG 174 A/U, RG 188 A/U, RG 316 /U S
Contact Dia.	0.7 mm (0.03in)
Wire Size/AWG	30 - 22
Gender	Standard



## Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	67.36 g

## Cable fixation

Jacket cable outside diameter [mm]	2.00 - 22.60 mm
------------------------------------	-----------------

## Drawings

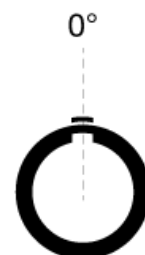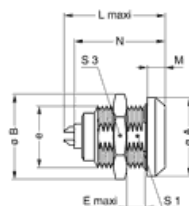

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egg-3k-846-cll1.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-cll1.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Dimensions

	<b>e</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>N</b>	<b>S1</b>	<b>S3</b>	<b>A</b>	<b>B</b>
mm.	M24x1.0	11	36.2	6	33.6	22.5	30	31	34.5
in.		0.43	1.43	0.24	1.32	0.89	1.18	1.22	1.36

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egg-3k-846-cll1.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-cll1.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.