



Summary

[Request a quote](#)

[Catalog](#)

Coax	1
Socket / Receptacle	Socket / Receptacle - Elbow
Locking system	Push-pull
Size	1
Matching parts	FFS.01.250.DLAE31

Technical details

Electrical Configuration

Coax	1
Insert configuration value	1.25 - 1 Coax (50 Ohm)

Form & Material

Shell style / Model id	EPL.01 - Elbow receptacle for printed circuit
Socket / Receptacle	Elbow
Housing material	Brass (gold plated [ISO 27874]) shell, collet nut, brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female
Weight	3.17 g

https://www.lemo.com/int_en/epl-01-250-dln.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment


Environmental protection (IP rating)

IP50

Minimal temperature

-55°C / +230°C

Drawings

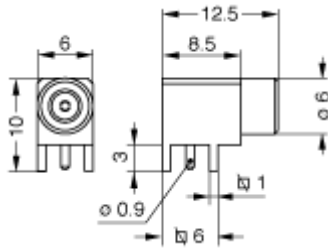

Dimensions

	A	L	M	B	C	D	N
mm.	6	12.5	8.5	6	6	10	3
in.	0.24	0.49	0.33	0.24	0.24	0.39	0.12

https://www.lemo.com/int_en/epl-01-250-dln.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.