



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	2
Wire Size/AWG	18 - 10
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.10 - 5.00 mm
Size	4S
Matching parts	ERA.4S.302.SLL
Series	S - Indoor Stepped Insert

Technical details

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
Insert configuration value	4S.302 - 2 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	35 Amps
Vtest	2100 V (AC), 3000 V (DC)
Contact Type	Solder
Bucket Dia.	3.7
Contact Dia.	4
Number of contacts Low Voltage	2
Wire Size/AWG	18 - 10



Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Weight	138.46 g

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.10 - 5.00 mm

Drawings

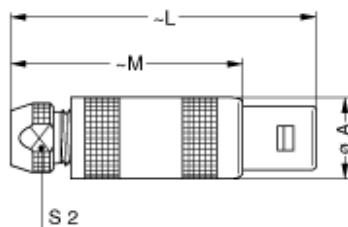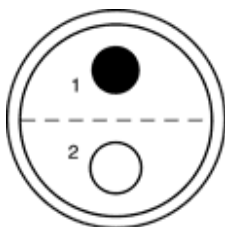

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	M	S2	L
mm.	24.8	59	19	77
in.	0.98	2.32	0.75	3.03









Recommended By Lemo

Accessories

Compatible cap [BFA.4S.100.NAS](#)

Tools

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.02.T20.047PGZE		grey	
CMN.02.T20.047PNZE			
CMN.02.T20.048QGZE	TPR (medical)	Grey	
120240	PVC	Black	
120250	PVC	Grey	
120501	PVC	Grey	
20260	PVC	Black	
2221	PVC	Black	
4082	PVC	Grey	

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.