



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	67
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 9.20 mm
Size	1R

Technical details

Electrical Configuration

Contact Termination Low voltage	Crimp
Insert configuration value	1R.367 - 67 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	0.5 Amps
Test voltage (kV rms) Contact-contact	0.6
Contact Type	Crimp
Number of contacts Low Voltage	67

https://www.lemo.com/int_en/fgg-1r-367-glc92.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FGG - Straight plug, key (G) or key (A), with cable collet
Plug	Straight
Housing material	Crastin® PBT (Polybutylene terephthalate), gray
Locking system	Push-pull
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Weight	17.22 g



Environment

Environmental protection (IP rating)	IP50
--------------------------------------	------

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.00 - 9.20 mm

Drawings

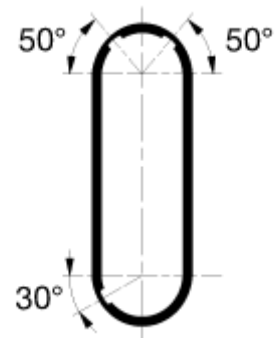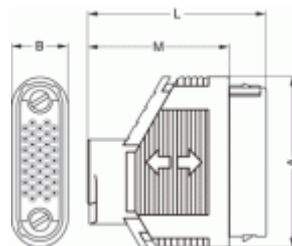

Dimensions

	A	B	L	M
mm.	37	12.5	39	31
in.	1.46	0.49	1.54	1.22

https://www.lemo.com/int_en/fgg-1r-367-glc92.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.