



Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	22
Wire Size/AWG	26 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.30 - 16.00 mm
Size	3F
Matching parts	FGN.3F.322.XLC
Series	F - Rugged Push-Pull

Technical details

https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/pen-3f-322-xlm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	6.1 mOhm
Insert configuration value	3F.322 - 22 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5.5 Amps
Vtest (contact-contact)	1700 V (AC), 2400 V (DC)
Vtest (contact-shell)	1450 V (AC), 2050 V (DC)
Contact retention	22 N
Contact Type	Crimp
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.14 mm ² (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Low Voltage	22
Wire Size/AWG	26 - 22
Gender	Standard

Form & Material

Shell style / Model id	PE - Straight receptacle, nut fixing (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Locking system	Push-pull
Keying	3 keys (beta=150, gamma=60, plug: male contacts, receptacle: female contacts)
Weight	14.02 g

https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/pen-3f-322-xlm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Motorsport, Security and Defence
Environmental protection (IP rating)	IP67
Minimal temperature	-15°C / +200°C
Climatical Category	15/200/21 (Aluminium shell)
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	max. 48 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.30 - 16.00 mm

Drawings

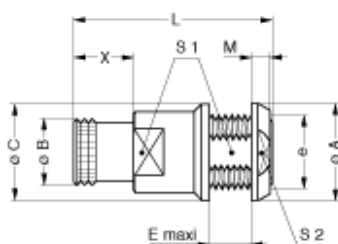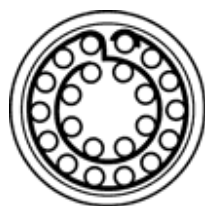

Dimensions

	S2	A	B	C	e	E	L	M	S1	X
mm.	19	22	16	22	M18x1.0	6.4	28.2	4	16.5	8
in.	0.75	0.87	0.63	0.87		0.25	1.11	0.16	0.65	0.31

Recommended By Lemo

Accessories

Replacement contact [EGG.0B.655.ZZM](#)

Tools

Positionner [DCE.91.070.BVM](#)

Extraction tool [DCF.93.070.4LT](#)

Crimp tool [DPC.91.701.V](#)

https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/pen-3f-322-xlm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.22.T30.054QGZE	TPR (medical)	Grey	

https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/pen-3f-322-xlm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.