



Summary

[Request a quote](#)

[Catalog](#)

Coax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.30 - 3.70 mm
Size	0S
Matching parts	FFA.0S.250.CTAC37
Series	S - Indoor Stepped Insert

Technical details

Electrical Configuration

Coax	1
Contact Termination Coax	Solder
Insert configuration value	0S.250 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	6 Amps
Impedance	50 Ohm
VSWR	$1.02 + 0.25 * f/\text{GHz}$
Vtest	3000 V (AC), 4200 V (DC)
Contact Type	Coaxial 50 Ohm (Solder)
Cable type	Cable type: A RG 178 B/U, RG 196 A/U, RG 188 A/U, RG 316 B/U, RG 174 A/U, HF-2114, RG 122 /U S
Bucket Dia.	1 mm (0.039in)
Contact Dia.	0.9 mm (0.035in)

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pfa-0s-250-ctlc37.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	PF - Fixed socket, with two nuts with cable collet (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female
Weight	8.75 g



Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Jacket cable outside diameter [mm]	3.30 - 3.70 mm

Drawings

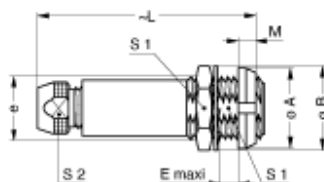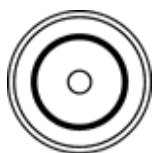

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pfa-0s-250-ctlc37.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo


Accessories

Tools

Spanner wrench

[Socket for torque wrench DCM.0S.M09.4](#)

Cables

Cable PartNumber	Material	Colour	Cable image
18000	PTFE	Brown	
CCX.95.RG1.80BU36M	PTFE	Brown	
CCX.95.RG1.95AU37B	PFA	White	

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pfa-0s-250-ctlc37.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.