



Summary

[Request a quote](#)

[Catalog](#)

Coax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.90 - 6.50 mm
Size	1S
Matching parts	FFA.1S.250.CTAC66
Series	S - Indoor Stepped Insert

Technical details

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-1s-250-ctlc66.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Coax	1
Contact Termination Coax	Solder
Insert configuration value	1S.250 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	12 Amps
Impedance	50 Ohm
VSWR	$1.01 + 0.23 * f/\text{GHz}$
Vtest	3000 V (AC), 4200 V (DC)
Contact Type	Coaxial 50 Ohm (Solder)
Cable type	Cable type: A RG 178 B/U, RG 196 A/U, RG 188 A/U, RG 316 B/U, RG 174 A/U, HF-2114, RG 122 /U S
Bucket Dia.	1.4 mm (0.055in)
Contact Dia.	1.6 mm (0.063in)


Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.90 - 6.50 mm

Drawings

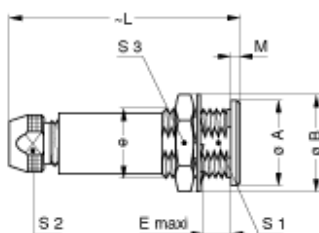

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-1s-250-ctic66.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	e	E	L	M	S1	S2	S3	C
mm.	14	16	M12x1.0	7.5	40.5	1.5	10.5	8.5	14	6.2
in.	0.55	0.63		0.3	1.59	0.06	0.41	0.33	0.55	0.24

Recommended By Lemo





Accessories

Tools

Spanner wrench

[DCD.1S.ZZZ.PA085](#)

Cables

Cable PartNumber	Material	Colour	Cable image
159580	PVC	Black	
62000	PVC	Black	
CCX.50.RG0.58AU61J	PVC	Yellow	
CCX.75.RG0.59BU62N	PVC	Black	
CCX.93.RG0.62AU62N	PVC	Black	

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-1s-250-ctlc66.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.