

Image for illustrative purpose only

概要

[見積もりを依頼する](#)

[audio video](#)

[LEMO connectors Audio Video Broadcast industries](#)

Nb of contacts Coax	1
Locking system	Push-pull
Size	0A

https://www.lemo.com/int_jp/abf-0a-275-cta.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Insert configuration value	0A.275 - 1 Coax (75 Ohm)
Insulator	T: PTFE
Impedance	75 Ohms


Form & Material

Shell style / Model id	ABF - Adapter from LEMO plug to BNC receptacle
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Grey
Weight	10.28 g

Environment

Environmental sealing (IP rating)	IP50
Endurance	>1000 mating cycles
Salt Spray Corrosion	>1000 hr

図面

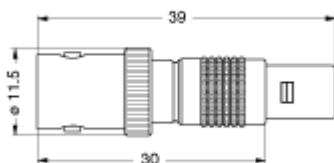

https://www.lemo.com/int_jp/abf-0a-275-cta.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.