



Image for illustrative purpose only

概要

見積もりを依頼する

BKT series

| | |
|------|-------------------|
| Size | 2K |
| シリーズ | K - Outdoor keyed |

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/bfg-2k-100-nps.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details



Form & Material

| | |
|------------------------|---|
| Shell style / Model id | BFG - Cap for plug (G key) |
| Housing material | Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces |
| Keying | G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Colour | Grey |
| Weight | 18.07 g |

Environment

| | |
|-----------------------------------|---|
| Technical domain | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental sealing (IP rating) | IP68 |
| Temperature range | -50°C / +135°C |
| Climatic Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Salt Spray Corrosion | >144 hr |

図面

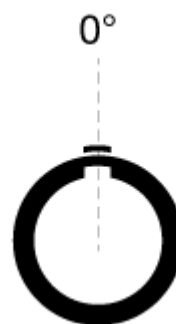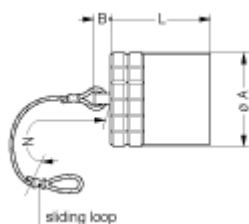

寸法

| | A | B | L | N |
|----------|------|------|------|------|
| mm. | 19.5 | 6 | 17.5 | 85 |
| になっています。 | 0.77 | 0.24 | 0.69 | 3.35 |

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/bfg-2k-100-nps.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.