

Special



Image for illustrative purpose only

概要

見積もりを依頼する

SE series

Size

0S

シリーズ

S - Indoor Stepped Insert

https://www.lemo.com/int_jp/solutions/originals/s-indoor-stepped-insert/bre-0s-200-kpsn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Insulator P: PEHD


Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	No keying
Colour	Black
Weight	4.48 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +135°C
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

図面

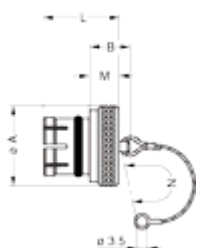

No keying

寸法

	A	B	L	M	N
mm.	10	9.5	10.5	4.5	85
になっています。	0.39	0.37	0.41	0.18	3.35

https://www.lemo.com/int_jp/solutions/originals/s-indoor-stepped-insert/bre-0s-200-kpsn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.