



Image for illustrative purpose only

概要

見積もりを依頼する

f series

Application leaflet Security Defence

Size

4F

シリーズ

F - Rugged Push-Pull

https://www.lemo.com/int_jp/solutions/optima/f-rugged-push-pull/brf-4f-200-xav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BRF - Cap for receptacle
Housing material	Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Keying	No keying
Colour	Grey
Weight	21.59 g

Environment

Technical domain	Motorsport, Security and Defence
Environmental sealing (IP rating)	IP67
Temperature range	-15°C / +135°C
Climatic Category	15/200/21 (Aluminium shell)
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	max. 48 hr

図面

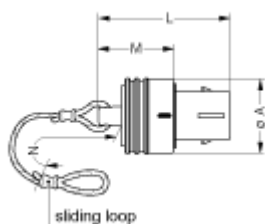

No keying

寸法

	A	L	M	N
mm.	26	30.3	20.1	120
になっています。	1.02	1.19	0.79	4.72

https://www.lemo.com/int_jp/solutions/optima/f-rugged-push-pull/brf-4f-200-xav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.