

Special



*Image for illustrative purpose only*

## 概要

見積もりを依頼する

---

BKT series

---

Size	4K
------	----

---

シリーズ	K - Outdoor keyed
------	-------------------

[https://www.lemo.com/int\\_jp/solutions/originals/k-outdoor-keyed/brf-4k-200-nav.html](https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/brf-4k-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRF - Cap for free receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	No keying
Colour	Grey
Weight	67.78 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +135°C
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

## 図面

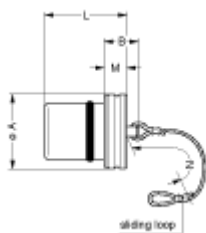

No keying

## 寸法

	A	B	L	M	N
mm.	30	20	30.5	10	120
になっています。	1.18	0.79	1.2	0.39	4.72

[https://www.lemo.com/int\\_jp/solutions/originals/k-outdoor-keyed/brf-4k-200-nav.html](https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/brf-4k-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.