

Special

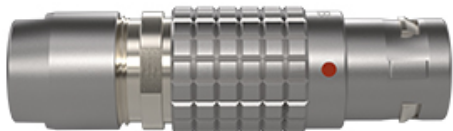


Image for illustrative purpose only

概要

見積もりを依頼する

thermocouple

Nb of contacts Thermocouple	4
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Size	2B
推奨適合部品	EGG.2B.902.CLJ
シリーズ	B - Indoor keyed

https://www.lemo.com/int_jp/solutions/originals/b-indoor-keyed/fgg-2b-902-cljf99.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Thermocouple	4
Contact Termination Thermocouple	Solder
Insert configuration value	2B.902/ThC - 2 Thermocouple Pairs
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	15 A
Gender	Standard

Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	26.89 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-40°C / +80°C
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

https://www.lemo.com/int_jp/solutions/originals/b-indoor-keyed/fgg-2b-902-cljf99.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

 


Cable termination protection

Standard back nut (no additional protection)

Fixation type

Cable collet

図面

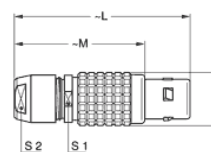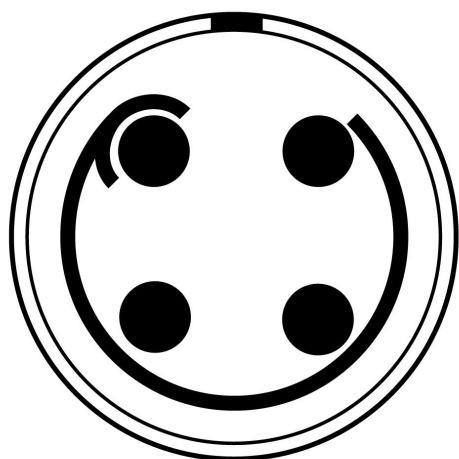

Contact 1, 3: Iron (+)
Contact 2, 4: Konstantan (-)

寸法

	A	L	M	S1	S2
mm.	15	50	38	13	12
になっています。	0.59	1.97	1.5	0.51	0.47

Lemoの推奨品

Accessories

Compatible cap

[BFG.2B.100.PCSG](#)

https://www.lemo.com/int_jp/solutions/originals/b-indoor-keyed/fgg-2b-902-cljf99.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.