

Standard



Image for illustrative purpose only

概要

見積もりを依頼する

Coax triax mixed en

Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	9.60 - 10.00 mm
Size	3K
推奨適合部品	EGG.3K.8H2.CJM1
シリーズ	K - Outdoor keyed

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/fgg-3k-8h2-cjcc101.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

R (max)	5.8 mOhm
Insulator	J: PEEK/PEEK
Rated current	2 A
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.34 mm ² (AWG 22)
Contact Dia.	0.7 mm (0.028in)
Gender	Standard

Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	68.51 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/fgg-3k-8h2-cjcc101.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	9.60 - 10.00 mm

図面

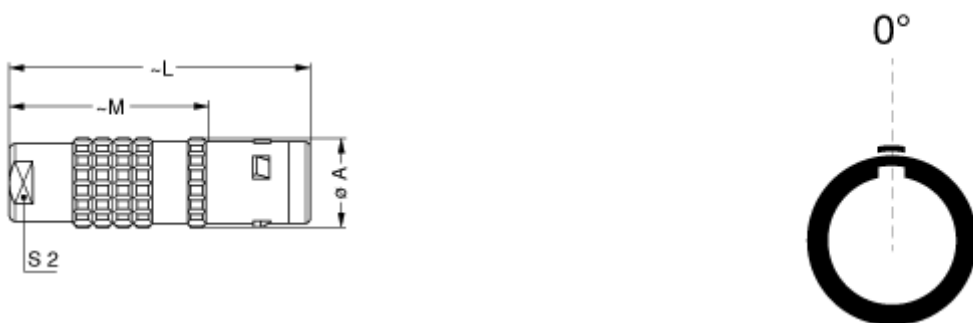

寸法

	A	L	S2	M
mm.	19	61	15	41
になっています。	0.75	2.4	0.59	1.61

Lemoの推奨品

Accessories

Replacement contact	FGG.3B.560.ZZC
Compatible cap	BFG.3K.100.NAS

Tools

Die Tool	DPE.99.103.8K
Positionner	DCE.91.093.BVC
Extraction tool	DCC.09.05B.LAG
Spanner wrench	DCD.3E.ZZZ.PA150

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/fgg-3k-8h2-cjcc101.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.