

Special



Image for illustrative purpose only

概要

見積もりを依頼する

Coax triax mixed en

Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	21.60 - 23.50 mm
Size	5B
推奨適合部品	EGJ.5B.893.CLC9 EGJ.5B.893.CLC5
シリーズ	B - Indoor keyed

https://www.lemo.com/int_jp/solutions/originals/b-indoor-keyed/fgj-5b-893-clmd239.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Insulator	L: PEEK (UL 94 / V-0/1.5)
-----------	---------------------------

Gender	Reverse Gender
--------	----------------

Form & Material

Shell style / Model id	FG - Straight plug, cable collet
------------------------	----------------------------------

Plug	Straight
------	----------

Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
------------------	---

Locking system	Push-pull
----------------	-----------

Keying	2 keys (alpha=37.5, plug: female contacts, receptacle: male contacts)
--------	---

Colour	Grey
--------	------

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
------------------	--

Environmental sealing (IP rating)	IP50
-----------------------------------	------

Endurance	5000 mating cycles
-----------	--------------------

Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
-------------------	---

Climatic Category	55/175/21
-------------------	-----------

Humidity (max)	<=95% [at 60 deg C /140 F]
----------------	----------------------------

Shielding (min)	75 dB (10 MHz)
-----------------	----------------

Shielding (min)	40 dB (1 GHz)
-----------------	---------------

Shock Resistance	100 g [6 ms]
------------------	---------------

Vibration	15 g [10 Hz - 2000 Hz]
-----------	------------------------

Salt Spray Corrosion	>1000 hr
----------------------	----------

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
------------------------------	--


Fixation type	Cable collet
---------------	--------------

Jacket cable outside diameter [mm]	21.60 - 23.50 mm
------------------------------------	------------------

https://www.lemo.com/int_jp/solutions/originals/b-indoor-keyed/fgj-5b-893-clmd239.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

図面

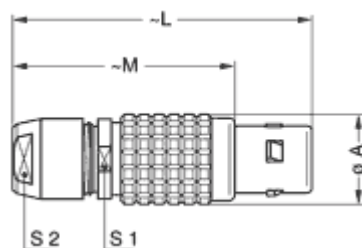

寸法

	S1	M	L	A	S2
mm.	31	78	103	35	30
になっています。	1.22	3.07	4.06	1.38	1.18

Lemoの推奨品

Accessories

Replacement contact [EGG.5B.660.ZZM](#)

Tools

Positionner [DCE.91.095.BVM](#)

Extraction tool [DCC.09.05B.LAG](#)

https://www.lemo.com/int_jp/solutions/originals/b-indoor-keyed/fgj-5b-893-clmd239.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.