

Standard



Image for illustrative purpose only

概要

見積もりを依頼する

BKT series

Size	3K
シリーズ	K - Outdoor keyed

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/gmf-3k-085-132en.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	GMF - Bend relief for plug
Keying	No keying
Variant	Gasket and O-ring in EPDM
Weight	23.08 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	No IP rating
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

図面

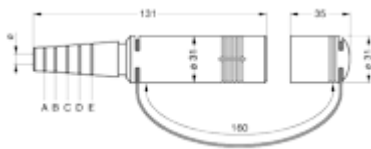

No keying

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/gmf-3k-085-132en.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.