

Standard



Image for illustrative purpose only

概要

見積もりを依頼する

fiber optic

Number of contacts Low Voltage	2
Nb of contacts Fiber optic	2
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.60 - 6.50 mm
Size	2K
推奨適合部品	FGG.2K.93B.CLAT66Z
シリーズ	K - Outdoor keyed

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/phg-2k-93b-cllt66z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	2
Contact Termination Low voltage	Solder
Nb of contacts Fiber optic	2
Contact Termination Fiber optic	Solder
Insulator	L: PEEK (UL 94 / V-0/1.5)
Contact Dia.	0.7
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	PH - Free receptacle, cable collet and nut for fitting a bend relief
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	55.04 g

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/phg-2k-93b-cllt66z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-40°C / +80°C
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	T type cable adapter
Jacket cable outside diameter [mm]	5.60 - 6.50 mm

図面

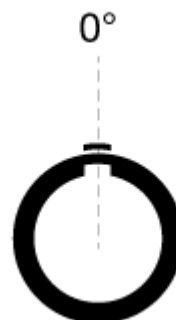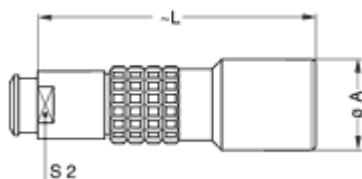

寸法

	L	A	S2
mm.	54	19	12
になっています。	2.13	0.75	0.47

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/phg-2k-93b-cllt66z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Lemoの推奨品

Accessories

Compatible cap

[BRF.2K.200.NAS](#)

https://www.lemo.com/int_jp/solutions/originals/k-outdoor-keyed/phg-2k-93b-clt66z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.