



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Nb of contacts Coax	1
Locking system	Push-pull
Size	0A

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Crimp
Insert configuration value	0A.275 - 1 Coax (75 Ohm)
Rated current	2 A
OHM	75

Form & Material

Shell style / Model id	ABG - Adapter from LEMO socket to BNC 75 ohms
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	22.88 g


Environment

Environmental sealing (IP rating)	IP50
Endurance	>1000 mating cycles
Salt Spray Corrosion	>144 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
------------------------------	--

Drawings

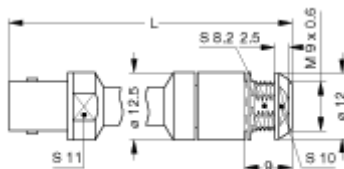

https://www.lemo.com/int_en/abg-0a-275-ntm.html

Dimensions

	L	A
mm.	62.5	12
in.	2.46	0.47

Recommended By Lemo

Tools

Spanner 2	DCM.65.106.AZ4
-----------	--------------------------------