



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system	Push-pull
Size	1

Technical details

Form & Material

Shell style / Model id	ARG.01 - Adapter
Housing material	Aluminum alloy (anodized) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	3.23 g


Environment

Environmental sealing (IP rating)	IP50
Endurance	>1000 mating cycles

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
------------------------------	--

Drawings

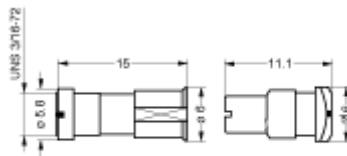

Dimensions

	A	L	M	B
mm.	6	15	11.1	5.8
in.	0.24	0.59	0.44	0.23

https://www.lemo.com/int_en/arg-01-f99-lne.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.