



## Summary

[Request a quote](#)

[Catalog](#)

Locking system	Threaded
Size	2V

## Technical details

### Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)


### Environment

Environmental protection (IP rating)	No IP rating
Minimal temperature	-20°C / +200°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>144 hr

[https://www.lemo.com/int\\_en/bfa-2v-100-nas.html](https://www.lemo.com/int_en/bfa-2v-100-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

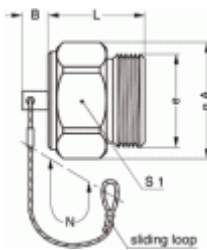

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>L</b>	<b>N</b>	<b>S1</b>
mm.	23.5	6	M20x1.0	17.5	85	22
in.	0.93	0.24		0.69	3.35	0.87

[https://www.lemo.com/int\\_en/bfa-2v-100-nas.html](https://www.lemo.com/int_en/bfa-2v-100-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.