



Image for illustrative purpose only

Summary

| | |
|---------------------------------|----------|
| Request a quote | |
| Catalog | |
| Locking system | Threaded |
| Size | 2V |

Technical details


Form & Material

| | |
|------------------------|--|
| Shell style / Model id | BFA - Cap for plug |
| Housing material | Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Threaded |
| Keying | 3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts) |
| Colour | Grey |
| Weight | 30.39 g |

Environment

| | |
|-----------------------------------|----------------|
| Environmental sealing (IP rating) | IP68 |
| Temperature range | -20°C / +135°C |
| Climatical Category | 20/200/21 |
| Pressure | 30 bars |

Drawings

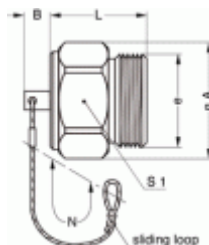

Dimensions

| | A | B | e | L | N | S1 |
|-----|------|------|---------|------|------|------|
| mm. | 23.5 | 6 | M20x1.0 | 17.5 | 85 | 22 |
| in. | 0.93 | 0.24 | | 0.69 | 3.35 | 0.87 |

https://www.lemo.com/int_en/bfa-2v-100-saz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.