



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size	3T
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bfa-3t-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BFA - Cap for plugs
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	A: 2 keys (alpha=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	27.24 g

Environment

Environmental sealing (IP rating)	IP66
Temperature range	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>144 hr

Drawings

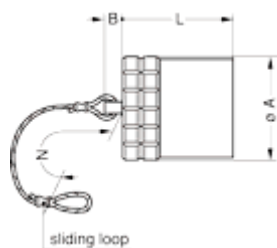

Dimensions

	A	B	L	N
mm.	24	6	17	120
in.	0.94	0.24	0.67	4.72

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bfa-3t-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.