



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

[Catalog](#)

---

Locking system

Threaded

---

Size

3V

[https://www.lemo.com/int\\_en/bfa-3v-100-nas.html](https://www.lemo.com/int_en/bfa-3v-100-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey

## Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	20/200/21
Pressure	30 bars
Salt Spray Corrosion	>144 hr

## Drawings

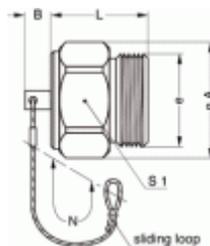

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>L</b>	<b>N</b>	<b>S1</b>
mm.	27.8	6	M24x1.0	22	120	26
in.	1.09	0.24		0.87	4.72	1.02

[https://www.lemo.com/int\\_en/bfa-3v-100-nas.html](https://www.lemo.com/int_en/bfa-3v-100-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.