



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Locking system	Threaded
Size	3V

Technical details


Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	52.63 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Pressure	30 bars

Drawings

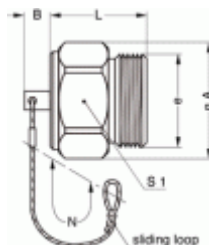

Dimensions

	A	B	e	L	N	S1
mm.	27.8	6	M24x1.0	22	120	26
in.	1.09	0.24		0.87	4.72	1.02

https://www.lemo.com/int_en/bfa-3v-100-saz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.