



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system

Threaded

Size

4V

https://www.lemo.com/int_en/bfa-4v-100-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	84.45 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>144 hr

Drawings

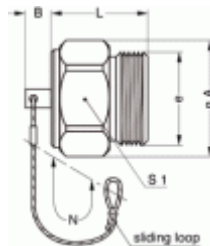

Dimensions

	A	B	e	L	N	S1
mm.	34.3	10	M30x1.0	22.5	120	32
in.	1.35	0.39		0.89	4.72	1.26

https://www.lemo.com/int_en/bfa-4v-100-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.