



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Locking system	Threaded
Size	4V

Technical details


Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	84.45 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Pressure	30 bars
Salt Spray Corrosion	>144 hr

Drawings

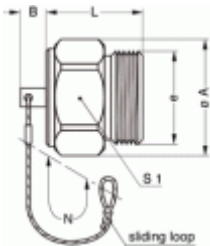

Dimensions

	A	B	e	L	N	S1
mm.	34.3	10	M30x1.0	22.5	120	32
in.	1.35	0.39		0.89	4.72	1.26

https://www.lemo.com/int_en/bfa-4v-100-naz.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.