



Image for illustrative purpose only

Summary

| | |
|---------------------------------|---------------------------|
| Request a quote | |
| Catalog | |
| Size | 6S |
| Series | S - Indoor Stepped Insert |

Technical details


Form & Material

| | |
|------------------------|--|
| Shell style / Model id | BFA - Cap for plug |
| Housing material | Brass (nickel plated [SAE AMS QQ N 290]) collet and crimping tube, brass (chrome plated [SAE AMS 2460]) collet nut |
| Keying | 3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts) |
| Colour | Grey |
| Weight | 118.83 g |

Environment

| | |
|-----------------------------------|---|
| Technical domain | Audio Video, Energy and Industrial, Semiconductor, Test and Measurement |
| Environmental sealing (IP rating) | IP68 |
| Temperature range | -50°C / +135°C |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Salt Spray Corrosion | >144 hr |

Drawings

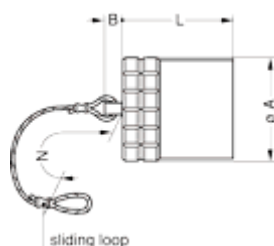

Dimensions

| | A | B | L | N |
|-----|------|------|-----|------|
| mm. | 46 | 10 | 33 | 150 |
| in. | 1.81 | 0.39 | 1.3 | 5.91 |

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bfa-6s-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.