



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size

MH

https://www.lemo.com/int_en/bfa-mh-100-xaz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	23.64 g

Environment

Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +125°C
Salt Spray Corrosion	max. 48 hr

Drawings

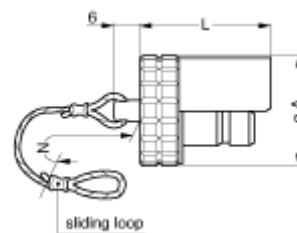

Dimensions

	A	L
mm.	25.4	30
in.	1	1.18

https://www.lemo.com/int_en/bfa-mh-100-xaz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.