



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

BKT series

---

Size	3K
Series	K - Outdoor keyed

---

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bfc-3k-100-nas.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfc-3k-100-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details



## Form & Material

Shell style / Model id	BFC - Cap for plug (C key)
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	C: 2 keys (alpha=60, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	25.03 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +135°C
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

## Drawings

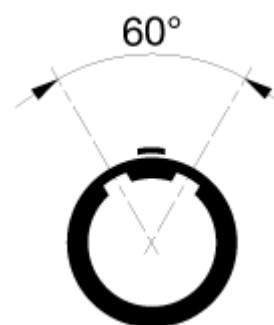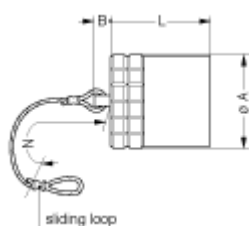

## Dimensions

	A	B	L	N
mm.	23	6	22	120
in.	0.91	0.24	0.87	4.72

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bfc-3k-100-nas.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfc-3k-100-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.