



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Size

00

[https://www.lemo.com/int\\_en/bfg-00-100-pcsg.html](https://www.lemo.com/int_en/bfg-00-100-pcsg.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BFG - Cap for plug
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	0.7 g

## Environment

Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +100°C

# Drawings

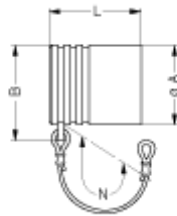

## Dimensions

	<b>A</b>	<b>B</b>	<b>L</b>	<b>N</b>
mm.	7.5	9.8	10	60
in.	0.3	0.39	0.39	2.36

[https://www.lemo.com/int\\_en/bfg-00-100-pcsg.html](https://www.lemo.com/int_en/bfg-00-100-pcsg.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.