

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

| | |
|--------|------------------|
| Size | 0B |
| Series | B - Indoor keyed |

Technical details



Form & Material

| | |
|------------------------|---|
| Shell style / Model id | BFG - Cap for plug |
| Housing material | POM (Polyoxymethylene) shell without treatment, silicone gasket |
| Keying | 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Weight | 0.92 g |

Environment

| | |
|-----------------------------------|--|
| Technical domain | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | IP50 |
| Temperature range | -50°C / +100°C |
| Climatic Category | 55/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |

Drawings

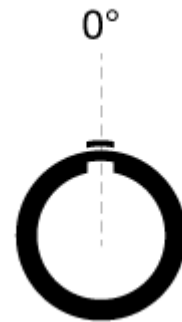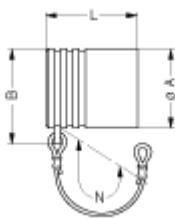

Dimensions

| | A | B | L | N |
|-----|------|------|------|------|
| mm. | 9.5 | 12 | 12.2 | 85 |
| in. | 0.37 | 0.47 | 0.48 | 3.35 |