



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Size	0T
Series	T - Small Outdoor keyed

Technical details



Form & Material

Shell style / Model id	BFG - Blanking cap for plugs
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	3.35 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>1000 hr

Drawings

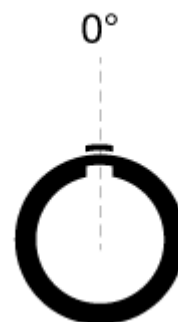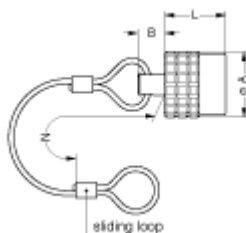

Dimensions

	A	B	L	N
mm.	9	5	11	85
in.	0.35	0.2	0.43	3.35

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bfg-0t-100-cas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.