



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system	Threaded
Size	0W
Series	W - Underwater

Technical details



Form & Material

Shell style / Model id	BFG - Cap for plug (G key)
Locking system	Threaded
Keying	G: 1 key (alpha=0, Plug: male contacts, Receptacle: female contacts)
Colour	Grey
Weight	13.64 g

Environment

Technical domain	Specialties and Other
Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Pressure	30 bars
Salt Spray Corrosion	>144 hr

Drawings

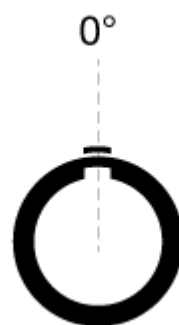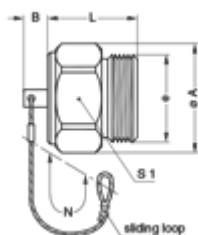

Dimensions

	A	B	e	L	N	S1
mm.	17.2	6	M14x1.0	12.5	85	16
in.	0.68	0.24		0.49	3.35	0.63

https://www.lemo.com/int_en/solutions/supreme/w-underwater/bfg-0w-100-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.