

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

Size	1B
Series	B - Indoor keyed

Technical details



Form & Material

Shell style / Model id	BFG - Cap for plug
Housing material	POM (Polyoxymethylene) shell without treatment, silicone gasket
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	1.26 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +100°C
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

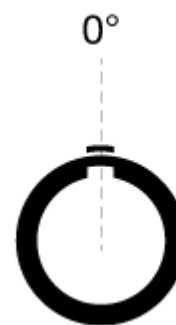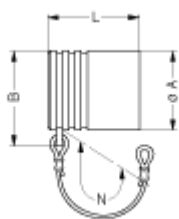

Dimensions

	A	B	L	N
mm.	12	15	13.8	85
in.	0.47	0.59	0.54	3.35