



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Locking system	Threaded
Size	3W
Series	W - Underwater

Technical details



Form & Material

Shell style / Model id	BFG - Cap for plug (G key)
Locking system	Threaded
Keying	G: 1 key (alpha=0, Plug: male contacts, Receptacle: female contacts)
Colour	Grey
Weight	56.06 g

Environment

Technical domain	Specialties and Other
Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Pressure	30 bars
Salt Spray Corrosion	>144 hr

Drawings

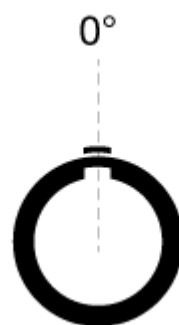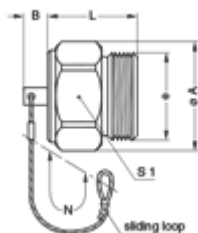

Dimensions

	A	B	e	L	N	S1
mm.	27.8	6	M24x1.0	22	120	26
in.	1.09	0.24		0.87	4.72	1.02

https://www.lemo.com/int_en/solutions/supreme/w-underwater/bfg-3w-100-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.