

Special



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

BKT series

---

|        |                   |
|--------|-------------------|
| Size   | 4K                |
| Series | K - Outdoor keyed |

---

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bfg-4k-100-ean.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfg-4k-100-ean.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details



## Form & Material

|                        |                                                                      |
|------------------------|----------------------------------------------------------------------|
| Shell style / Model id | BFG - Cap for plug (G key)                                           |
| Keying                 | G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Colour                 | Black                                                                |
| Weight                 | 13.86 g                                                              |

## Environment

|                                   |                                                                   |
|-----------------------------------|-------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental sealing (IP rating) | IP68                                                              |
| Temperature range                 | -55°C / +200°C (max. temperature valid for short periods of use.) |
| Climatic Category                 | 50/175/21                                                         |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]                                        |
| Shock Resistance                  | 100 g [ 6 ms]                                                     |
| Vibration                         | 15 g [10 Hz - 2000 Hz]                                            |

## Drawings

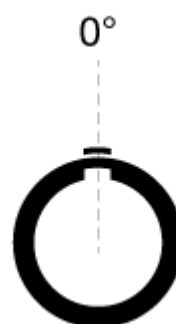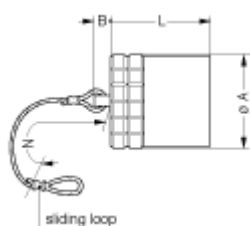

## Dimensions

|     | A    | B    | L    | N    |
|-----|------|------|------|------|
| mm. | 29   | 10   | 22.5 | 120  |
| in. | 1.14 | 0.39 | 0.89 | 4.72 |

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bfg-4k-100-ean.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfg-4k-100-ean.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.