



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system	Threaded
Size	4W
Series	W - Underwater

https://www.lemo.com/int_en/solutions/supreme/w-underwater/bfg-4w-100-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details



Form & Material

Shell style / Model id	BFG - Cap for plug (G key)
Locking system	Threaded
Keying	G: 1 key (alpha=0, Plug: male contacts, Receptacle: female contacts)
Colour	Grey
Weight	86.24 g

Environment

Technical domain	Specialties and Other
Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>144 hr

Drawings

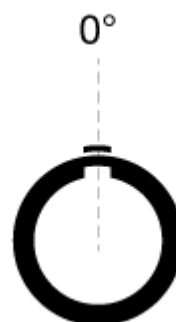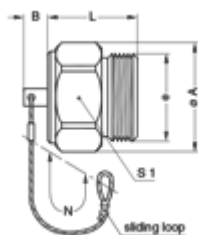

Dimensions

	A	B	e	L	N	S1
mm.	34.3	10	M30x1.0	22.5	120	32
in.	1.35	0.39		0.89	4.72	1.26

https://www.lemo.com/int_en/solutions/supreme/w-underwater/bfg-4w-100-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.