



Summary

[Request a quote](#)

[Catalog](#)

Size	5B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	BFG - Cap for plug (G key)
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	65.13 g



https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/bfg-5b-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental protection (IP rating)	No IP rating
Minimal temperature	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

Drawings

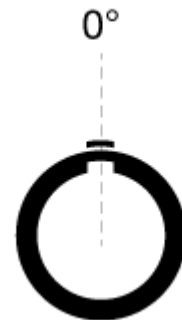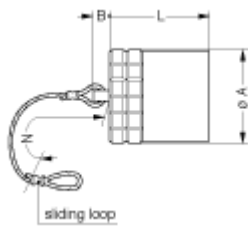

Dimensions

	A	B	L	N
mm.	36	10	27.2	150
in.	1.42	0.39	1.07	5.91

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/bfg-5b-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.