



Summary

[Request a quote](#)

[Catalog](#)

Size	5K
Series	K - Outdoor keyed

Technical details

Form & Material

Shell style / Model id	BFG - Cap for plug (G key)
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	96.56 g



Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	No IP rating
Minimal temperature	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfg-5k-100-sas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Drawings

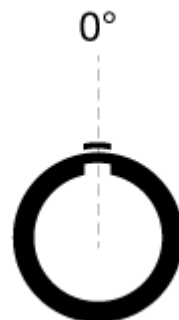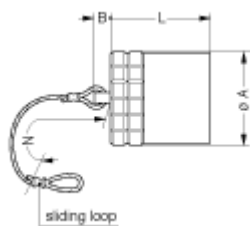

Dimensions

	A	B	L	N
mm.	44	10	27	150
in.	1.73	0.39	1.06	5.91

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfg-5k-100-sas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.