



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	7.40 - 24.20 mm
Size	LF
Series	F - Rugged Push-Pull

https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/bfg-lf-100-xaz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Form & Material

Shell style / Model id	BFG - Cap for plug (G key)
Housing material	Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	12.25 g


Environment

Technical domain	Motorsport, Security and Defence
Environmental sealing (IP rating)	IP67
Temperature range	-15°C / +135°C
Climatical Category	15/200/21 (Aluminium shell)
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	max. 48 hr

Cable fixation

Jacket cable outside diameter [mm]	7.40 - 24.20 mm
------------------------------------	-----------------

Drawings

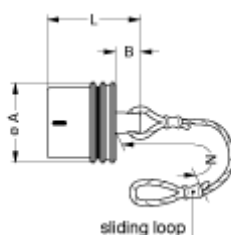

Dimensions

	A	L	M	N
mm.	30	8	24	120
in.	1.18	0.31	0.94	4.72

https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/bfg-lf-100-xaz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.