



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size	2K
Series	K - Outdoor keyed

Technical details


Form & Material

Shell style / Model id	BFL - Cap for plug (L key)
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Keying	2 keys (gamma=75, plug: female contacts, receptacle: male contacts)
Colour	Grey
Weight	18.83 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Drawings

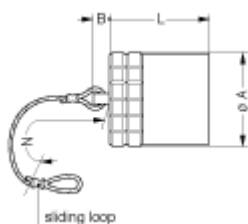

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bfl-2k-100-cas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	L	N
mm.	19.5	6	17.5	85
in.	0.77	0.24	0.69	3.35