



Summary

[Request a quote](#)

[Catalog](#)

Size	OK
Series	K - Outdoor keyed

Technical details

Form & Material

Shell style / Model id	BHG - Plug cap nut fixing or flange
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	7.71 g



https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bhg-0k-100-kas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	No IP rating
Minimal temperature	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Drawings

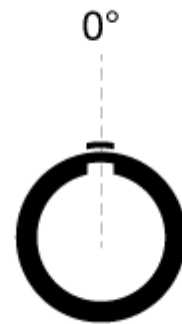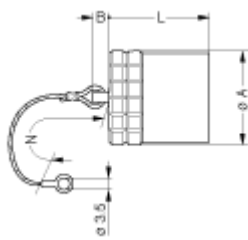

Dimensions

	A	B	L	N
mm.	14	6	12.5	85
in.	0.55	0.24	0.49	3.35

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bhg-0k-100-kas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.