

Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size

3T

Series

T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bhg-3t-100-kas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details



Form & Material

Shell style / Model id	BHG - Blanking cap for fixed plugs
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Black
Weight	7.73 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>1000 hr

Drawings

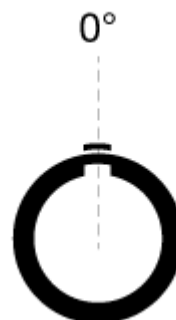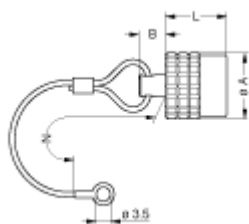

Dimensions

	A	B	L	N
mm.	17	6	17.6	120
in.	0.67	0.24	0.69	4.72

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bhg-3t-100-kas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.