



## Summary

[Request a quote](#)

---

[Catalog](#)

---

Size 3T

---

Series T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/bra-3t-200-ean.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bra-3t-200-ean.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRA - Blanking cap for fixed sockets
Keying	2 keys (alpha=30, plug: male contacts, receptacle: female contacts)
Colour	Black
Weight	8.57 g

## Environment

Environmental sealing (IP rating)	IP66
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]

## Drawings

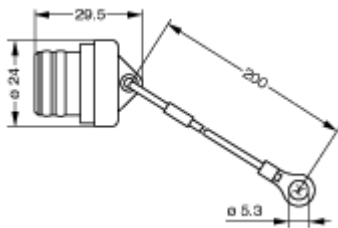

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/bra-3t-200-ean.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bra-3t-200-ean.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.