



Image for illustrative purpose only

Summary

| | |
|---------------------------------|------------------|
| Request a quote | |
| Catalog | |
| Size | 2B |
| Series | B - Indoor keyed |

Technical details


Form & Material

| | |
|------------------------|---|
| Shell style / Model id | BRD - Cap for free receptacle |
| Housing material | POM (Polyoxymethylene) shell without treatment, silicone gasket |
| Keying | No keying |
| Weight | 1.25 g |

Environment

| | |
|-----------------------------------|--|
| Technical domain | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | IP61 |
| Temperature range | -50°C / +100°C |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |

Drawings

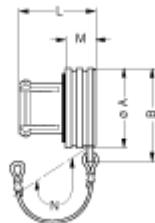

No keying

Dimensions

| | A | B | L | M | N |
|-----|------|------|------|------|------|
| mm. | 18 | 21 | 14.5 | 6 | 85 |
| in. | 0.71 | 0.83 | 0.57 | 0.24 | 3.35 |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/brd-2b-200-pcsn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.