



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

[Catalog](#)

---

Size	2B
------	----

---

Series	B - Indoor keyed
--------	------------------

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/brd-2b-200-pcsn.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/brd-2b-200-pcsn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRD - Cap for free receptacle
Housing material	POM (Polyoxymethylene) shell without treatment, silicone gasket
Keying	No keying
Weight	1.25 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP61
Temperature range	-55°C / +100°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

## Drawings

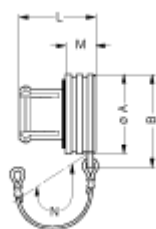

No keying

## Dimensions

	<b>A</b>	<b>B</b>	<b>L</b>	<b>M</b>	<b>N</b>
mm.	18	21	14.5	6	85
in.	0.71	0.83	0.57	0.24	3.35

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/brd-2b-200-pcsn.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/brd-2b-200-pcsn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.